


B-01-A1

Aliases (UDLB00001A1000)

Differential Mode Chokes - Signal, KEMET, BEAD L, Through-Hole, Normal Mode

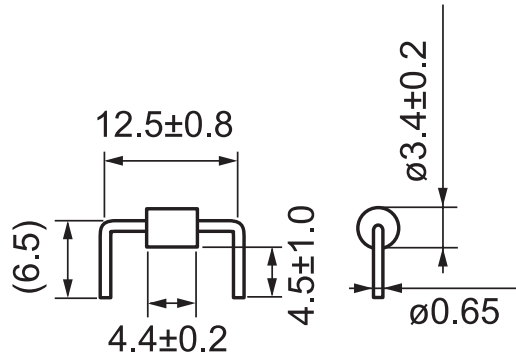

(Tin coated soft copper wire)

Click [here](#) for the 3D model.

General Information

Series	BEAD L
Style	Through-Hole
RoHS	Yes

Dimensions

D	3.4mm +/-0.2mm
L	12.5mm +/-0.8mm
H	6.5mm NOM
LL	6.5mm NOM
L2	4.4mm +/-0.2mm
F	0.65mm NOM

Packaging Specifications

Packaging	Bulk
Packaging Quantity	250
Typical Component Weight	300 mg

Specifications

Temperature Range	-20/+70°C
-------------------	-----------

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.