


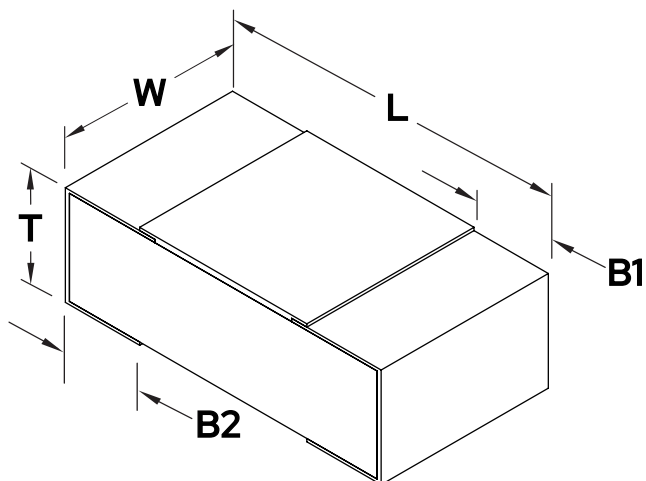

Click [here](#) for the 3D model.

General Information

Supplier	YAGEO
Series	RL
Style	SMD Chip
Description	Current Sensor resistor
RoHS	Yes
Termination	Tin
Case Code (EIA / mm)	1218 / 3246

Specifications

Resistance	604 mOhms
Resistance Tolerance	1%
Power	1 W (70C)
Temp. Coefficient	-/+250 ppm/C
Temperature Range	-55/+155°C
Voltage DC	0.8 V (Max Continuous Voltage at Full Rated Power)

Dimensions

L	3.05mm +/-0.15mm
W	4.6mm +/-0.2mm
T	0.55mm +/-0.1mm
B1	0.45mm +/-0.25mm
B2	0.5mm +/-0.25mm

Packaging Specifications

Packaging	T&R, 178mm
-----------	------------