


# SPF-100-1R1A010

Aliases (UDLSPF0100010B)

Obsolete

Scheduled EOL - Suggested Alternate Part SCR-100-1R2A010JH

Common Mode Chokes - Signal, KEMET, SPF, SMD, Common Mode, 1,000 uH

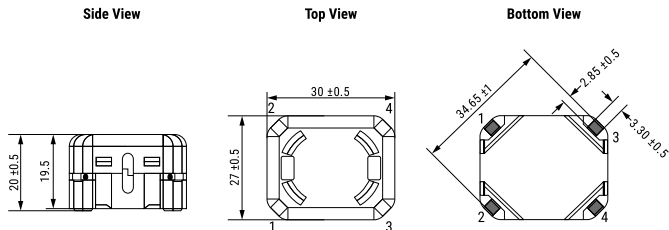

Click [here](#) for the 3D model.

## General Information

Series	SPF
Style	SMD
RoHS	Yes

## Dimensions

L	30mm +/-0.5mm
W	27mm +/-0.5mm
H	20mm +/-0.5mm

## Packaging Specifications

Packaging	Tray
Packaging Quantity	35
Typical Component Weight	26 g

## Specifications

Voltage DC	150 VDC
Inductance	1 mH
Temperature Range	-40/+120°C
DC Resistance	10 mOhms (per Line MAX)

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.